

















**Specifications** (measured @ Ta= 25°C, nom. Vin, full load and after warm-up unless otherwise stated)

**DIMENSION and PHYSICAL CHARACTERISTICS**

Parameter	Type	Value
Material	baseplate	non-conductive black plastic, (UL94 V-0)
	case	non-conductive black plastic, (UL94 V-0)
	potting	silicone (UL94 V-0)
Dimension (LxWxH)		31.8 x 20.3 x 10.2mm
Weight		0.15g typ.

**Dimension Drawing (mm)**  
**"A" Pinning**

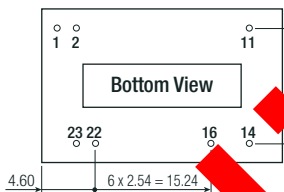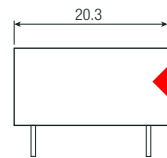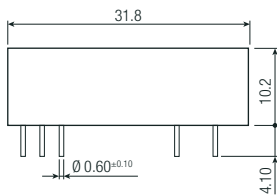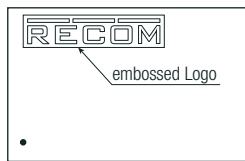

**Pin Connections**

Pin	Single	Dual
1	CTRL (option)	CTRL (option)
2	-Vin	-Vin
14	NC	-Vout
16	+Vout	+Vout
22	-Vout	Com
23	+Vin	+Vin

Tolerance:  
XX.X ± 0.5mm  
XX.XX ± 0.25mm

**PACKAGING INFORMATION**

Parameter	Type	Value
Packaging Dimension (LxWxH)	tube	520.0 x 22.7 x 18.3mm
Packaging Quantity	tube	15pcs
Storage Temperature Range		-55°C to +125°C
Storage Humidity		95% RH max.

The product information and specifications may be subject to changes even without prior written notice. The product has been designed for various applications; its suitability lies in the responsibility of each customer. The products are not authorized for use in safety-critical applications without RECOM's explicit written consent. A safety-critical application is an application where a failure may reasonably be expected to endanger or cause loss of life, inflict bodily harm or damage property. The applicant shall indemnify and hold harmless RECOM, its affiliated companies and its representatives against any damage claims in connection with the unauthorized use of RECOM products in such safety-critical applications.